

PM3000i

Inverter Generator

Model P0080600 UPC: 696471078916
(50 ST)


Features

- **POWERDIAL™ Recoil Start** (Off/Run/Cold Start) offers three settings integrated into one simple-to-use dial.
- **Ultra Quiet Performance** with fully enclosed case.
- **RPM+** automatically adjusts engine RPM based on load demand to reduce sound emissions and conserve fuel.
- **Clean, stable power** with less than 3% total harmonic distortion for safe operation of sensitive electronics.
- **1.06 Gallon Fuel Tank** provides a 5.8 hour run time at 25% load.
- **Lightweight Design** with built-in handle for easy portability.
- **Powermate OHV engine** provides consistent power for multiple applications.
- **Low-oil level shutdown** prevents engine damage.



AC Maximum Output Starting Watts 3000
AC Rated Output Running Watts 2300

50-State Control Panel

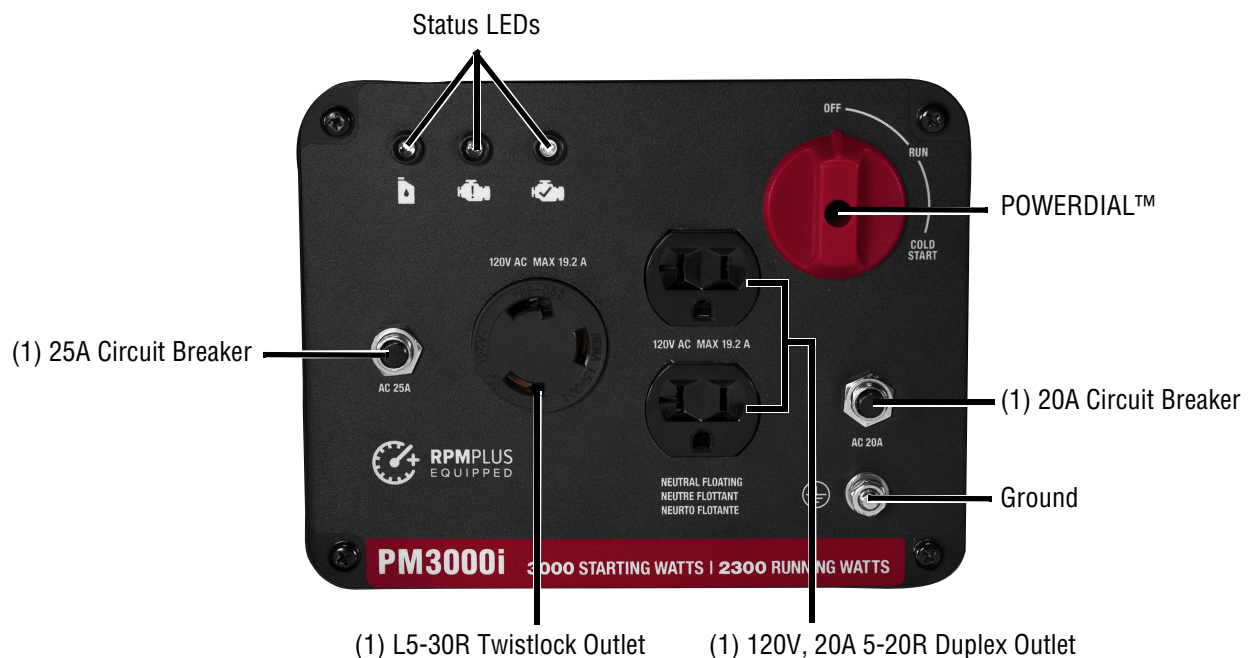

PM3000i

Specifications

Product Series	PM3000i
Model (Configuration)	P0080600 (50 ST)
AC Maximum Output Starting Watts	3000
AC Rated Output Running Watts	2300
Rated AC Voltage	120 VAC
Rated AC Frequency	60 Hz
Rated 120 VAC Amperage	19.2
Total Harmonic Distortion	Less than 3%
Engine Displacement	149cc
Engine Type	OHV
Engine RPM	Variable
Recommended Oil	10W-30 / SAE30
Lubrication Method	Splash
Choke Location	Integrated into POWERDIAL™
Fuel Shut Off	Integrated into POWERDIAL™
Starting Method	Recoil Pull Start
Low Oil Shutdown	Low Level
Floating Neutral	Yes

Start Switch Type	POWERDIAL™
Start Switch Location	On Control Panel
Fuel Tank Capacity Gal (L)	1.06 (4.0)
Run Time at 25% of Rated Load (Hours)	5.8
Run Time at 50% of Rated Load (Hours)	4.5
Warranty- Residential	3 Year Ltd
Warranty- Commercial	90 Days

Dimensions and Weights

Length in (mm)	22.2 (565)
Width in (mm)	13.3 (339)
Height in (mm)	18.4 (467)
Carton Length in (mm)	23.6 (600)
Carton Width in (mm)	13.4 (340)
Carton Height in (mm)	20.8 (530)
Unit Weight lbs (kg)	59.5 (27)
Shipping Weight lbs (kg)	65 (29.5)

