

PM7500

Portable Generator

Model P0081600 UPC: 696471080391
(EPA/49 ST/CSA)


Features

- **POWERDIAL™ Recoil Start** (Off/Run/Cold Start) offers three operation settings integrated into one simple-to-use dial.
- **Large Capacity Steel Fuel Tank** provides durability and up to a 14 hour run-time at 25% load.
- **Powered by Generac 420cc OHV Engine** provides consistent power for multiple applications.
- **10" Never Flat Wheels** for easy transportation.
- **Hour Meter** tracks run-time and maintenance intervals.
- **Low-Oil Level Shutdown** prevents engine damage.
- **Fuel Gauge** allows users to keep track of gasoline levels.
- **Ergonomic Frame** for easy portability.
- **Covered Outlets** provide protection and keep out debris.



AC Maximum Output Starting Watts 7500
AC Rated Output Running Watts 6000

49-State/CSA Control Panel

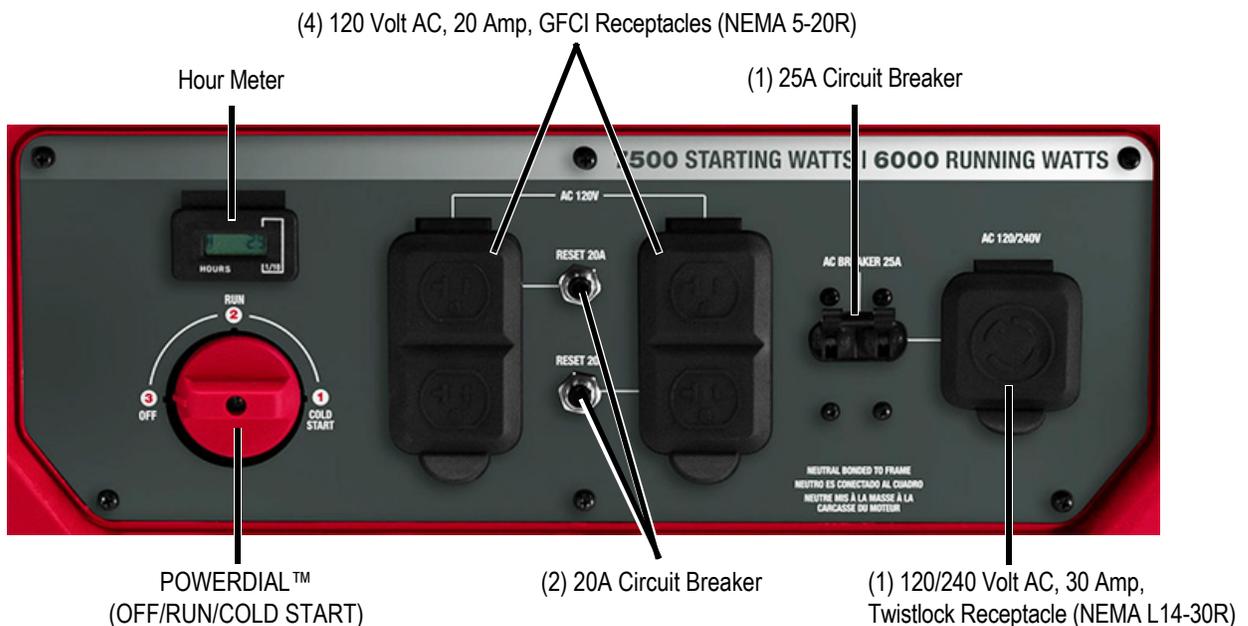

PM7500

Specifications

Product Series	PM7500
Model (Configuration)	P0081600 (EPA/49 ST/CSA)
AC Maximum Output Starting Watts	7500
AC Rated Output Running Watts	6000
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated 120/240 VAC Amperage	50 / 25
Engine Displacement	420cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30
Lubrication Method	Splash
Choke Location	On Control Panel
Fuel Shut Off	On Fuel Tank
Starting Method	Recoil Pull Start
Low Oil Shutdown	Low Level
Neutral Bonded to Ground	Yes
Start Switch Type	POWERDIAL™
Start Switch Location	On Control Panel

Fuel Tank Capacity Gal (L)	8 (30.3)
Run Time at 25% of Rated Load (Hours)	14
Run Time at 50% of Rated Load (Hours)	11
Warranty- Residential	3 Year Ltd
Warranty- Commercial	90 Day

Dimensions and Weights

Extended Length in (mm)	48.7 (1238)
Length in (mm)	31 (789)
Width in (mm)	27 (685)
Height in (mm)	26.4 (670)
Carton Length in (mm)	32.7 (830)
Carton Width in (mm)	23 (585)
Carton Height in (mm)	24.2 (615)
Unit Weight lbs (kg)	170 (77)
Shipping Weight lbs (kg)	187 (84.9)

