

PM3800

Portable Generator

Model P0081100 UPC: 696471080339
(EPA/49 ST/CSA)


Features

- **POWERDIAL™ Recoil Start** (Off/Run/Cold Start) offers three operation settings integrated into on simple-to-use dial.
- **Large Capacity Steel Fuel Tank** provides durability and up to a 21 hour run-time at 25% load.
- **Powered by Generac 212cc OHV Engine** provides consistent power for multiple applications.
- **Ergonomic Frame** for easy portability.
- **Hour Meter** tracks run-time and maintenance intervals.
- **Low-Oil Level Shutdown** prevents engine damage.
- **Fuel Gauge** allows users to keep track of gasoline levels.
- **Covered Outlets** provide protection and keep out debris.



AC Maximum Output Starting Watts 3800
AC Rated Output Running Watts 3000

49-State/CSA Control Panel

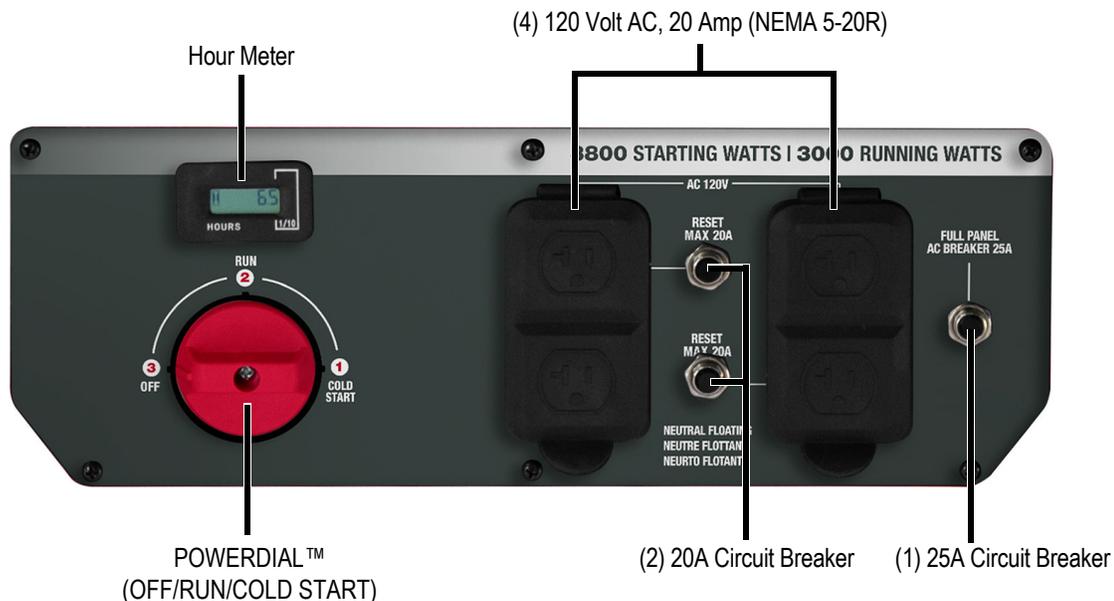

PM3800

Specifications

Product Series	PM3800
Model (Configuration)	P0081100 (49 ST/CSA)
AC Maximum Output Starting Watts	3800
AC Rated Output Running Watts	3000
Rated AC Voltage	120 VAC
Rated AC Frequency	60 Hz
Rated 120 VAC Amperage	25
Engine Displacement	212cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30
Lubrication Method	Splash
Choke Location	Integrated into POWERDIAL™
Fuel Shut Off	On Fuel Tank
Starting Method	Recoil Pull Start
Low Oil Shutdown	Low Level
Floating Neutral	Yes
Start Switch Type	POWERDIAL™
Start Switch Location	On Control Panel

Fuel Tank Capacity Gal (L)	5 (18.9)
Run Time at 25% of Rated Load (Hours)	21
Run Time at 50% of Rated Load (Hours)	14
Warranty- Residential	3 Year Ltd
Warranty- Commercial	90 Day

Dimensions and Weights

Length in (mm)	23.8 (605)
Width in (mm)	18.1 (460)
Height in (mm)	19.1 (485.5)
Carton Length in (mm)	24.6 (625)
Carton Width in (mm)	19.3 (490)
Carton Height in (mm)	20.1 (510)
Unit Weight lbs (kg)	96 (43.5)
Shipping Weight lbs (kg)	103 (46.6)

Portability Kit (sold separately)	Model P0080700
Handle Style	Single Folding / Locking
Wheel Type	8" Never Flat Wheels
Carton Length in (mm)	20.4 (518)
Carton Width in (mm)	10.8 (275)
Carton Height in (mm)	3 (75)
Unit Weight lbs (kg)	6.7 (3)

