

PM9400E

Portable Generator

Features

- **One-Touch Electric Start** with auto-choke provides reliable, hassle-free startups.
- **Large Capacity Steel Fuel Tank** provides durability and up to a 13 hour run time at 25% load.
- **Powered by Generac 420cc OHV Engine** provides consistent power for multiple applications.
- **10" Never Flat Wheels** for easy transportation.
- **Hour Meter** tracks run-time and maintenance intervals.
- **Low-Oil Level Shutdown** prevents engine damage.
- **Fuel Gauge** allows users to keep track of gasoline levels.
- **Covered Outlets** provide protection and keep out debris.


Model P0080301 (49 ST / CSA) UPC: 696471077827

Model P0081500 (50 ST) UPC: 696471080384



AC Maximum Output Starting Watts 9400
AC Rated Output Running Watts 7500

49-State/CSA / 50-State Control Panel

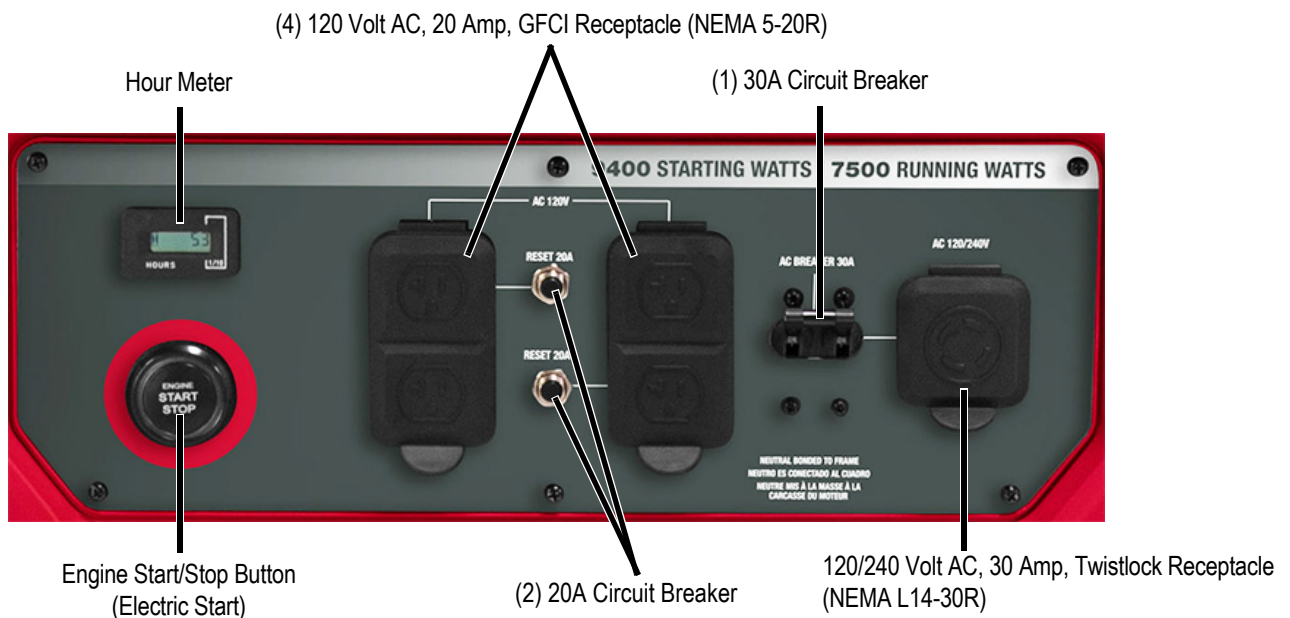

PM9400E

Specifications

Product Series	PM9400E
Model (Configuration)	P0080301 (49 ST/CSA) P0081500 (50 ST)
AC Maximum Output Starting Watts	9400
AC Rated Output Running Watts	7500
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated 120/240 VAC Amperage	62.5 / 31.3
Engine Displacement	420cc
Engine Type	OHV
Engine RPM	3600
Recommended Oil	10W-30
Lubrication Method	Splash
Choke Location	Auto-Choke (manual lever on engine for recoil start mode)
Fuel Shut Off	On Fuel Tank
Starting Method	One-Touch Electric Start / Recoil
Low Oil Shutdown	Low Level
Neutral Bonded to Ground	Yes

Start Switch Type	Push Button
Start Switch Location	On Control Panel
Fuel Tank Capacity Gal (L)	8 (30.3)
Run Time at 25% of Rated Load (Hours)	13
Run Time at 50% of Rated Load (Hours)	10
Warranty- Residential	3 Year Ltd
Warranty- Commercial	90 Day

Dimensions and Weights

Extended Length in (mm)	48.7 (1238)
Length in (mm)	31 (789)
Width in (mm)	27 (685)
Height in (mm)	26.4 (670)
Carton Length in (mm)	32.7 (830)
Carton Width in (mm)	23 (585)
Carton Height in (mm)	24.2 (615)
Unit Weight lbs (kg)	188 (85.3)
Shipping Weight lbs (kg)	204 (92.5)

